


Availability

The connections **union nut with female or male thread (code FV, MV)** are available for the following GEMÜ diaphragm valves: 601, 605, 611, 612, 615, 625, 650, 653, 654, 671, 673, 687, 695

Dimensions

Union nut with female and male thread (code FV, MV)

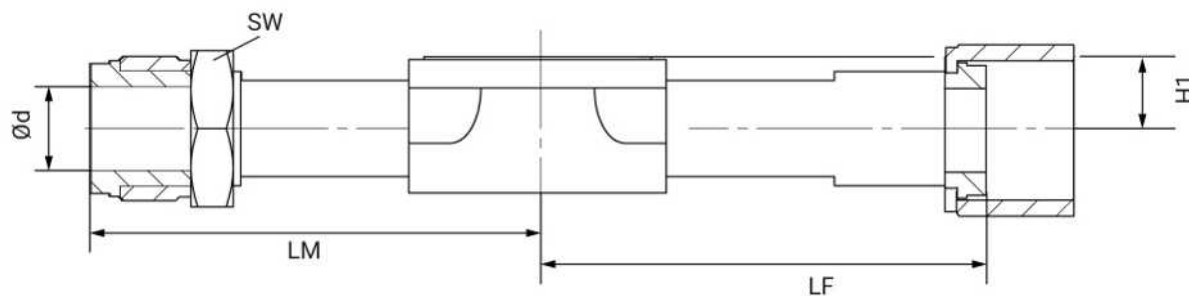

Connection type union nut with female thread (code FV) ¹⁾

MG	DN	NPS	Ød	H1	LF	SW
8	8	1/4"	9.1	8.5	40.9	3/4"
	10	3/8"	15.5	8.5	51.0	1 1/16"
	15	1/2"	15.5	8.5	41.4	1 1/16"
10	10	3/8"	15.5	12.5	62.5	1 1/16"
	15	1/2"	15.5	12.5	52.9	1 1/16"
	20	3/4"	22.6	12.5	85.7	1 1/2"
25	20	3/4"	22.6	19.0	92.2	1 1/2"
	25	1"	30.5	19.0	99.3	1 3/4"

Connection type union nut with male thread (code MV) ¹⁾

MG	DN	NPS	Ød	H1	LM	SW
8	8	1/4"	9.1	8.5	55.9	5/8"
	10	3/8"	15.5	8.5	68.1	15/16"
	15	1/2"	15.5	8.5	58.4	15/16"
10	10	3/8"	15.5	12.5	79.6	15/16"
	15	1/2"	15.5	12.5	69.9	15/16"
	20	3/4"	22.6	12.5	85.7	1 5/16"
25	20	3/4"	22.6	19.0	92.2	1 5/16"
	25	1"	30.5	19.0	99.3	1 5/8"

Dimensions in mm

1) Connection type

Code FV: Pipe union with flush stainless steel sealing contour union nut with female thread

Code MV: Pipe union with flush stainless steel sealing contour union nut with male thread