


Availability

The connections **union nut with female or male thread (code FV, MV)** are available for the following GEMÜ diaphragm valves: 601, 605, 611, 612, 615, 625, 650, 653, 654, 671, 673, 687, 695

Dimensions

Union nut with female and male thread (code FV, MV)

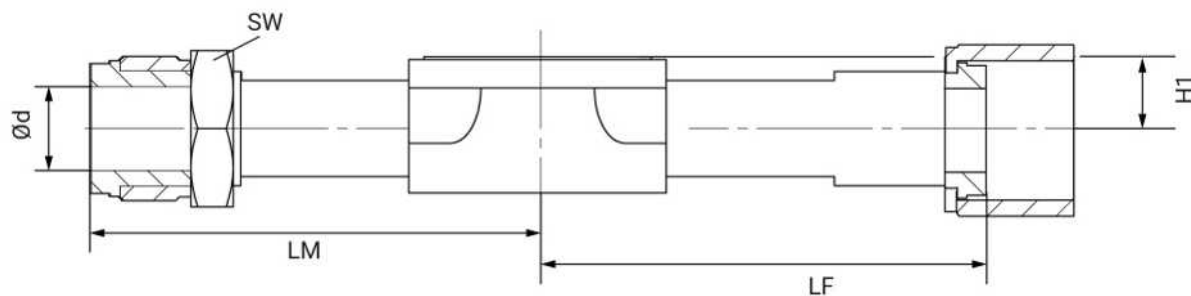

Connection type union nut with female thread (code FV) ¹⁾

MG	DN	NPS	Ød	H1	LF	SW
8	8	1/4"	3.58	3.35	16.10	3/4"
	10	3/8"	6.10	3.35	2.01	1 1/16"
	15	1/2"	6.10	3.35	16.30	1 1/16"
10	10	3/8"	6.10	4.92	24.61	1 1/16"
	15	1/2"	6.10	4.92	20.83	1 1/16"
	20	3/4"	8.90	4.92	33.74	1 1/2"
25	20	3/4"	8.90	7.48	36.30	1 1/2"
	25	1"	12.01	7.48	39.09	1 3/4"

Connection type union nut with male thread (code MV) ¹⁾

MG	DN	NPS	Ød	H1	LM	SW
8	8	1/4"	3.58	3.35	22.01	5/8"
	10	3/8"	6.10	3.35	26.81	15/16"
	15	1/2"	6.10	3.35	22.99	15/16"
10	10	3/8"	6.10	4.92	31.34	15/16"
	15	1/2"	6.10	4.92	27.52	15/16"
	20	3/4"	8.90	4.92	33.74	1 5/16"
25	20	3/4"	8.90	7.48	36.30	1 5/16"
	25	1"	12.01	7.48	39.09	1 5/8"

Dimensions in inch

1) Connection type

Code FV: Pipe union with flush stainless steel sealing contour union nut with female thread

Code MV: Pipe union with flush stainless steel sealing contour union nut with male thread